

Toggle Clamps

Hold Down, Horizontal Handle (Flange Base)

1N=0.101972kgf

Hold Down, Horizontal Handle (Flange Base)

Part Number	MC01-5
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	196
Weight (g)	30
Arm Open-Close Angle	71°
Handle Open-Close Angle	72°
Accessory	Steel Bolt
Unit Price	


Hold Down, Horizontal Handle (Flange Base)

Part Number	MC01-6	MC01-S6
Body Material	SS400	SUS304
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	196	
Weight (g)	30	
Arm Open-Close Angle	75°	
Handle Open-Close Angle	82°	
Accessory	Steel Bolt	Stainless Steel Bolt
Unit Price		


Hold Down, Horizontal Handle (Flange Base)

Part Number	MC01-7
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	294
Weight (g)	100
Arm Open-Close Angle	72°
Handle Open-Close Angle	74°
Accessory	Steel Bolt
Unit Price	


MC01-5

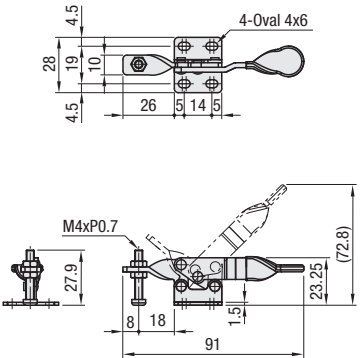

MC01-6
MC01-S6 (Stainless Steel)

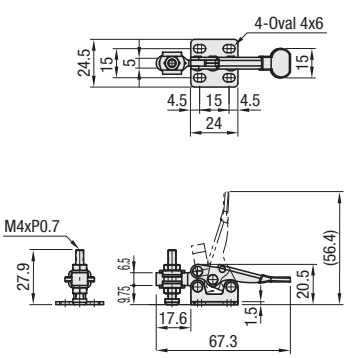

MC01-7

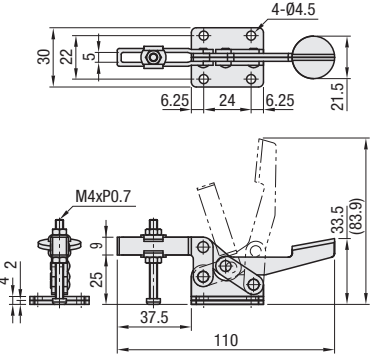


Hold Down, Horizontal Handle (Flange Base)

Part Number	MC01-8	MC01-S8
Body Material	SS400	SUS304
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	2450	
Weight (g)	210	
Arm Open-Close Angle	77°	
Handle Open-Close Angle	85°	
Accessory	Steel Bolt	Stainless Steel Bolt
Unit Price		


Hold Down, Horizontal Handle (Flange Base)

Part Number	MC01-9	MC01-S9
Body Material	SS400	SUS304
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	2744	
Weight (g)	435	
Arm Open-Close Angle	79°	
Handle Open-Close Angle	86°	
Accessory	Steel Bolt	Stainless Steel Bolt
Unit Price		

MC01-8
MC01-S8 (Stainless Steel)

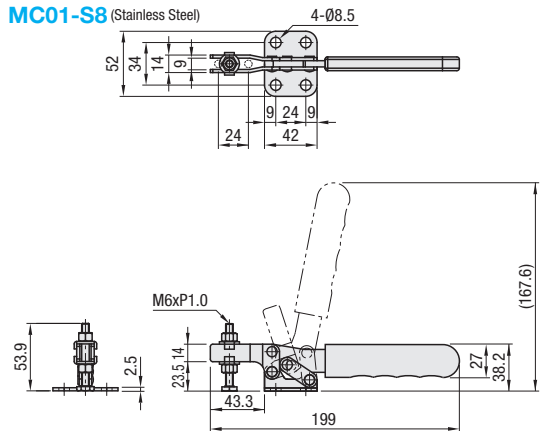

MC01-9
MC01-S9 (Stainless Steel)

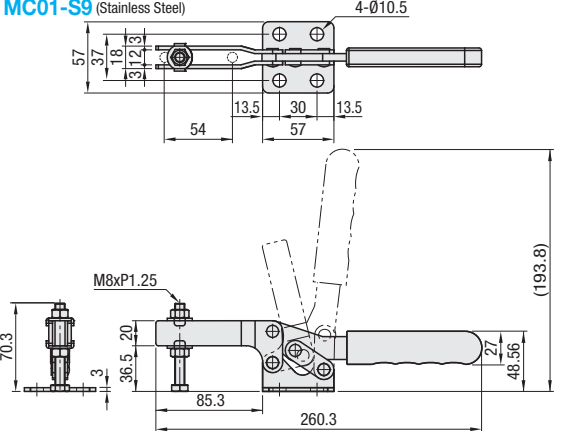

Ordering Example

Part Number
MC01-6
MC01-S8

Toggle Clamps

Hold Down, Horizontal Handle (Straight Base / Side Mount Base / Flange Base)

1N=0.101972kgf


Hold Down, Horizontal Handle (Straight Base)

Part Number	MC01-8S
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	2450
Weight (g)	210
Arm Open-Close Angle	77°
Handle Open-Close Angle	85°
Accessory	Steel Bolt
Unit Price	


Hold Down, Horizontal Handle (Straight Base)

Part Number	MC01-9S
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	2744
Weight (g)	435
Arm Open-Close Angle	79°
Handle Open-Close Angle	86°
Accessory	Steel Bolt
Unit Price	

MC01-8S
(Straight Base)

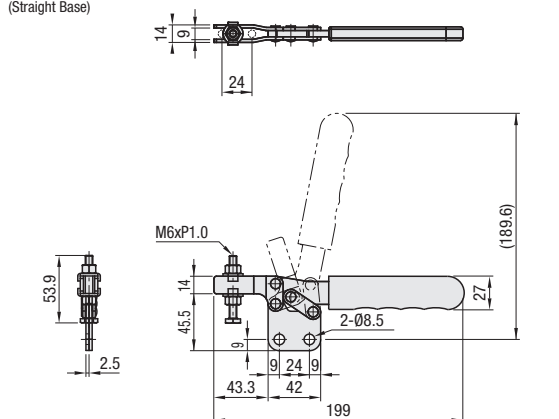

MC01-9S
(Straight Base)

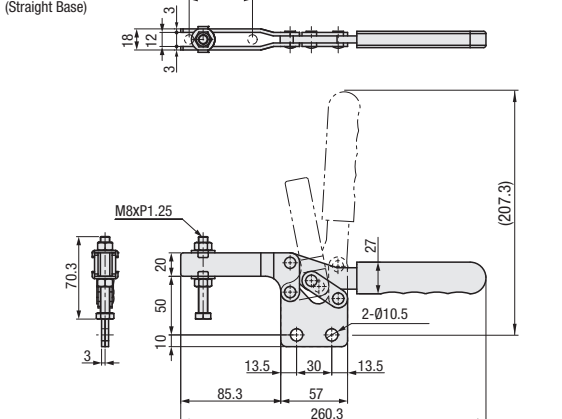

Hold Down, Horizontal Handle (Side Mount Base)

Part Number	MC01-11
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	2500
Weight (g)	210
Arm Open-Close Angle	77°
Handle Open-Close Angle	85°
Accessory	Steel Bolt
Unit Price	


Hold Down, Horizontal Handle (Flange Base)

Part Number	MC01-12
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	2800
Weight (g)	530
Arm Open-Close Angle	86°
Handle Open-Close Angle	75°
Accessory	Steel Bolt
Unit Price	


Hold Down, Horizontal Handle (Flange Base)

Part Number	MC01-13
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	5000
Weight (g)	635
Arm Open-Close Angle	66°
Handle Open-Close Angle	83°
Accessory	Steel Bolt
Unit Price	


MC01-11

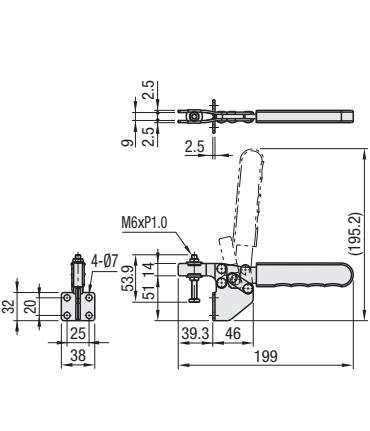

MC01-12

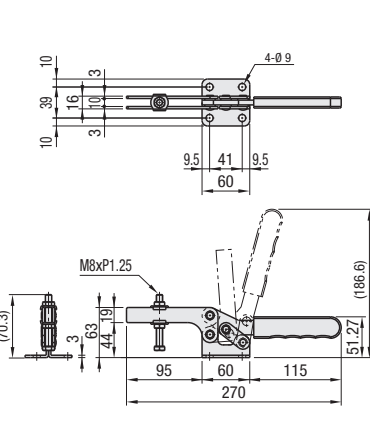

MC01-13

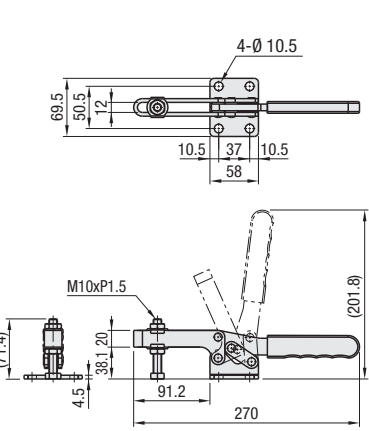

Ordering Example

Part Number
MC01-11
MC01-12



Example

Combination of these app. examples can be selected on our website.
Selection Procedure Details [P87](#)

e-Catalog Search Keyword [#MA474](#) Search

* Enter the search keyword in the search box on e-Catalog. The search result will be shown in "Modular Assembler" area.

