

Toggle Clamps

Hold Down, Vertical Handle, Long Arm (Straight Base)

1N=0.101972kgf

Hold Down, Vertical Handle, Long Arm (Straight Base)




Part Number	MC04-1LS
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	186
Weight (g)	75
Arm Open-Close Angle	100°
Handle Open-Close Angle	56°
Accessory	Bolt with Rubber Material: NBR Hardness: Shore A70
Unit Price	

Hold Down, Vertical Handle, Long Arm (Straight Base)




Part Number	MC04-2LS
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	392
Weight (g)	175
Arm Open-Close Angle	95°
Handle Open-Close Angle	60°
Accessory	Bolt with Rubber Material: NBR Hardness: Shore A70
Unit Price	

MC04-1LS

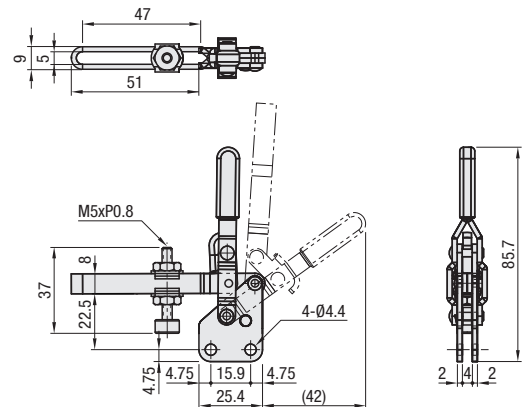

MC04-2LS

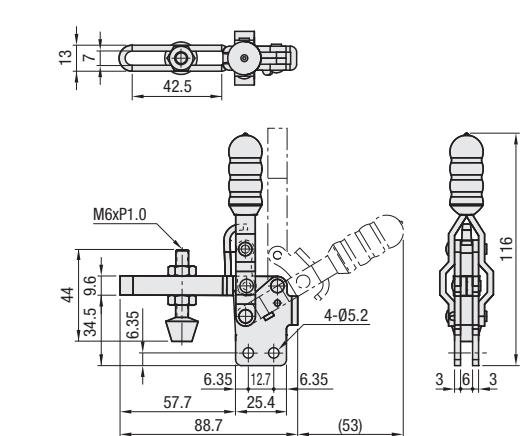

Hold Down, Vertical Handle, Long Arm (Straight Base)




Part Number	MC04-3LS
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	784
Weight (g)	370
Arm Open-Close Angle	100°
Handle Open-Close Angle	56°
Accessory	Bolt with Rubber Material: NBR Hardness: Shore A70
Unit Price	

Hold Down, Vertical Handle, Long Arm (Straight Base)




Part Number	MC04-4LS
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	1078
Weight (g)	815
Arm Open-Close Angle	112°
Handle Open-Close Angle	61°
Accessory	Bolt with Rubber Material: NBR Hardness: Shore A70
Unit Price	

MC04-3LS

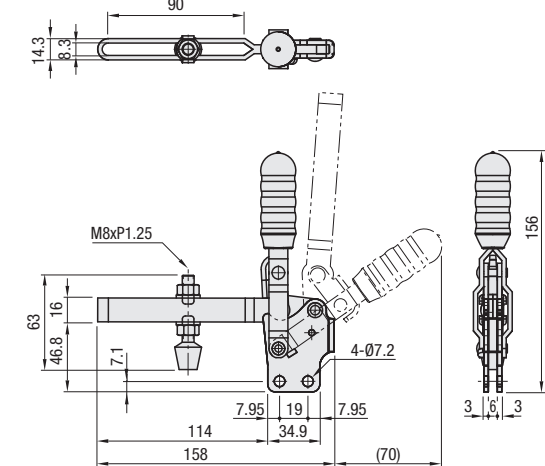

MC04-4LS

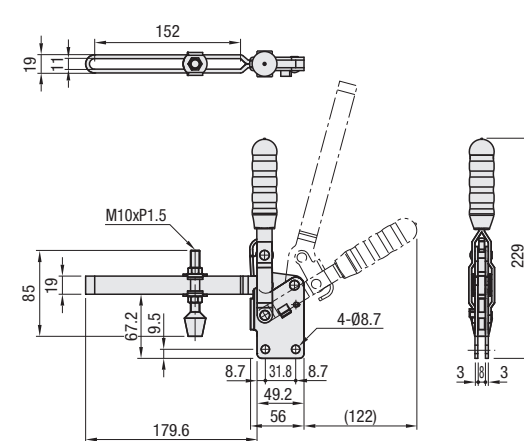

Ordering Example Part Number MC04-3LS

Toggle Clamps

Hold Down, Vertical Handle (Flange Base)

1N=0.101972kgf

Hold Down, Vertical Handle (Flange Base)




Part Number	MC04-6	MC04-S6
Body Material	SS400	SUS304
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	294	-
Weight (g)	40	-
Arm Open-Close Angle	80°	-
Handle Open-Close Angle	88°	-
Accessory	Bolt with Rubber Material: NBR Hardness: Shore A70	With Rubber Stainless Steel Bolt
Unit Price		

Hold Down, Vertical Handle (Flange Base)




Part Number	MC04-7	MC04-S7
Body Material	SS400	SUS304
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	980	-
Weight (g)	200	-
Arm Open-Close Angle	120°	-
Handle Open-Close Angle	72°	-
Accessory	Steel Bolt	Stainless Steel Bolt
Unit Price		

MC04-6
MC04-S6 (Stainless Steel)

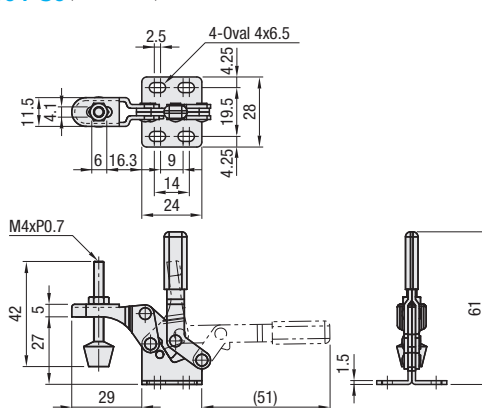

MC04-7
MC04-S7 (Stainless Steel)

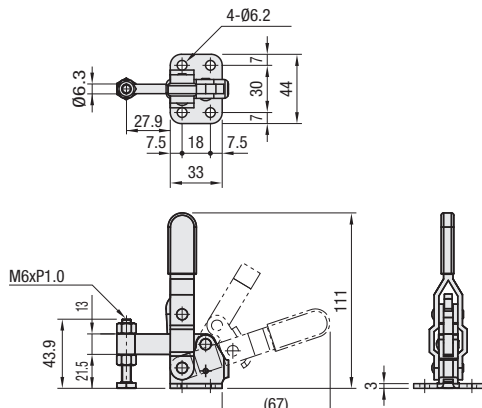

Hold Down, Vertical Handle (Flange Base)




Part Number	MC04-8	MC04-S8
Body Material	SS400	SUS304
Surface Treatment	Trivalent Chromate	-
Tightening Force (N)	1470	-
Weight (g)	370	-
Arm Open-Close Angle	94°	-
Handle Open-Close Angle	54°	-
Accessory	Steel Bolt	Stainless Steel Bolt
Unit Price		

Hold Down, Vertical Handle (Flange Base)




Part Number	MC04-9
Body Material	SS400
Surface Treatment	Trivalent Chromate
Tightening Force (N)	1960
Weight (g)	420
Arm Open-Close Angle	110°
Handle Open-Close Angle	64°
Accessory	Steel Bolt
Unit Price	

MC04-8
MC04-S8 (Stainless Steel)

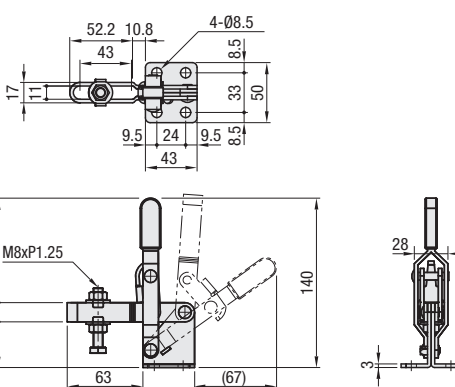


MC04-9

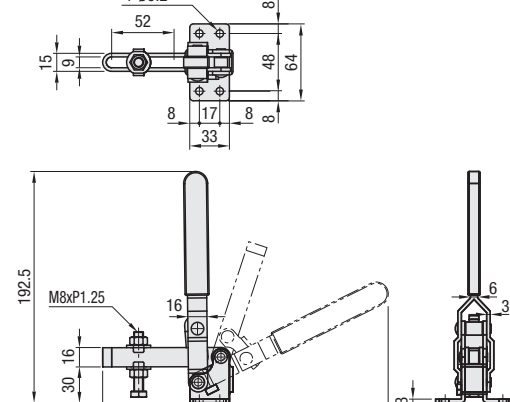

Ordering Example Part Number MC04-6

ex Example Combination of these app. examples can be selected on our website. Selection Procedure Details P87

e-Catalog Search Keyword #MA555 Search

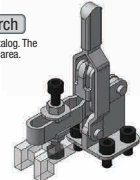

* Enter the search keyword in the search box on e-Catalog. The search result will be shown in "Modular Assembler" area.