 



High Pressure Screw Fittings

Equal Dia. / Reducing

Sockets RoHS10




Type	Material
SGPPSH	S25C
SUTPSH	SCS13A

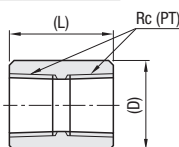

Hex Sockets RoHS10




Type	Material
SGPSH	S25C

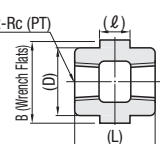

Elbows RoHS10




Type	Material
SGPPEH	S25C
SUPESH	SCS13A

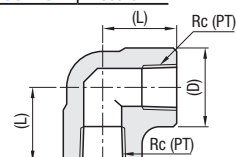

45° Elbows RoHS10




Type	Material
SGPHEH	S25C
SUTHEH	SCS13A

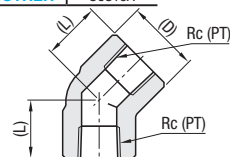

Male/Female Elbows RoHS10




Type	Material
SGPELH	S25C
SUTELH	SCS13A

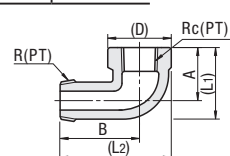


Tees RoHS10




Type	Material
SGPPTH	S25C
SUTPTH	SCS13A

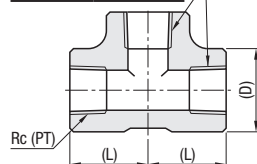

Plugs RoHS10

 

Type	Material
SGPPPJ	S25C
SUPPPJ	SCS13A

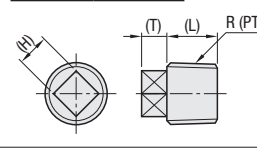

Part Number		SGPPSH		SUTPSH		SGPPSH		SUTPSH	
Type	No.	Rc (PT)	(D)	(L)	(D)	(L)	Unit Price	Volume Discount Rate	Unit Price
SGPPSH	6A	1/8	19	22	19	26	1 ~ 4 pcs.	5 ~ 20 pcs.	1 ~ 4 pcs.
	8A	1/4	22	25	22	28			
	10A	3/8	28	28	25	33			
	15A	1/2	32	32	32	37			
	20A	3/4	38	38	38	42			
SUTPSH	25A	1	46	45	45	45			
	32A	1 1/4	58	50	55	52			
	40A	1 1/2	63	55	65	56			
	50A	2	76	60	75	66			

For orders larger than indicated quantity, please check with WOS.

Part Number		SGPSH		SUTPUJ		SGPPUJ		SUTPUJ	
Type	No.	Rc (PT)	B	(D)	(L)	Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate
SGPSH	8A	1/4	22	8	22	28	1 ~ 4 pcs.	5 ~ 20 pcs.	1 ~ 4 pcs.
	10A	3/8	27	9	27	33			
	15A	1/2	32	9	32	37			
	20A	3/4	38	12	38	42			
	25A	1	46	13	46	45			
SUTPUJ	32A	1 1/4	58	14	56	52			

For orders larger than indicated quantity, please check with WOS.

Part Number		SGPPEH		SUPESH		SGPPEH		SUPESH	
Type	No.	Rc (PT)	(D)	(L)	(D)	(L)	Unit Price	Volume Discount Rate	Unit Price
SGPPEH	6A	1/8	23	21.6	23	21.6	1 ~ 4 pcs.	5 ~ 20 pcs.	1 ~ 4 pcs.
	8A	1/4	23	21.6	23	21.6			
	10A	3/8	27	25.5	27	25.5			
	15A	1/2	34	28.9	34	28.9			
	20A	3/4	39	33.1	39	33.1			
SUPESH	25A	1	47	38.2	47	38.2			
	32A	1 1/4	56	44.6	56	45.0			
	40A	1 1/2	63	51.1	63	50.8			
	50A	2	76	58.0	76	60.1			

For orders larger than indicated quantity, please check with WOS.

Part Number		SGPHEH		SUTHEH		SGPHEH		SUTHEH	
Type	No.	Rc (PT)	(D)	(L)	(D)	(L)	Unit Price	Volume Discount Rate	Unit Price
SGPHEH	8A	1/4	23	18.4	23	18.4	1 ~ 4 pcs.	5 ~ 20 pcs.	1 ~ 4 pcs.
	10A	3/8	27	18.9	27	18.9			
	15A	1/2	34	24.1	34	24.1			
	20A	3/4	39	26.7	39	26.7			
	25A	1	47	30.3	47	30.3			
SUTHEH	32A	1 1/4	56	35.5	56	35.5			
	40A	1 1/2	63	39.6	63	39.6			
	50A	2	76	46.4	76	46.4			

For orders larger than indicated quantity, please check with WOS.

Part Number		R FC (PT)	SGPELH					SUTELH					SGPELH		SUTELH	
Type	No.		(D)	(L1)	(L2)	A	B	(D)	(L1)	(L2)	A	B	Unit Price 1 - 9 pcs.	Volume Discount Rate 10 - 30 pcs.	Unit Price 1 - 19 pcs.	Volume Discount Rate 20-50pcs.
SGPELH	8A	1/4	24	30	41	21	27	25	32.5	45	22	32				
	10A	3/8	24	35	41	25	28	33	39.5	55	25	38				
	15A	1/2	32	41	51	29	35	38	44.5	61	28	41				
SUTELH	20A	3/4	36	47	59	33	40	46	55.5	72	35	48				
	25A	1	46	57	74	38	48	56	70.5	86	44	57				
	32A	1 1/4	56	70.5	86	44	57									
	40A	1 1/2	63	76	86	44	57									
	50A	2	76	86	44	57										

For orders larger than indicated quantity, please check with WOS.

Part Number		SGPPTH		SUTPTH		SGPPTH		SUTPTH	
Type	No.	Rc (PT)	(D)	(L)	(D)	(L)	Unit Price	Volume Discount Rate	Unit Price
SGPPTH	8A	1/4	23	21.6	23	21.6	1 ~ 4 pcs.	5 ~ 20 pcs.	1 ~ 4 pcs.
	10A	3/8	27	25.5	27	25.5			
	15A	1/2	34	28.9	34	28.9			
	20A	3/4	39	33.1	39	33.1			
	25A	1	47	38.2	47	38.2			
SUTPTH	32A	1 1/4	56	44.6	56	45.0			
	40A	1 1/2	63	51.1	63	50.8			
	50A	2	76	58.0	76	60.1			

For orders larger than indicated quantity, please check with WOS.


Part Number		SGPPPJ		SUPPPJ		SGPPPJ		SUPPPJ	
Type	No.	R (PT)	(L)	(T)	(H)	(L)	(T)	(H)	Unit Price
SGPPPJ	8A	1/4	11	9	9	11	7	9	1 ~ 4 pcs.
	10A	3/8	12	10	12	12	9	12	5 ~ 20 pcs.
	15A	1/2	15	11	14	15	10	14	1 ~ 4 pcs.
	20A	3/4	17	12	17	17	11	17	5 ~ 20 pcs.
	25A	1	19	13	19	20	12	21	
SUPPPJ	32A	1 1/4	22	14	23	22	13	23	
	40A	1 1/2	22	15	26	22	14	28	
	50A	2	26	16	32	26	15	33	

For orders larger than indicated quantity, please check with WOS.

Hex Nipples RoHS10




Type	Material
SGPNRJ	S25C
SUTNRJ	SCS13A

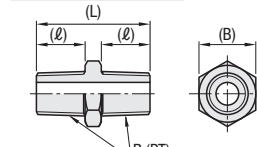

Unions (With O-Ring) RoHS10




Type	Main Body	O-Ring
SGPPUJ	S25C	Nitrile Rubber
SUTPUJ	SCS13A	

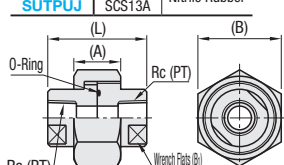

Reducing Sockets RoHS10




Type	Material
SGPSDJ	S25C
SUTSSJ	SCS13A

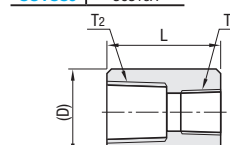

Reducing Nipples RoHS10




Type	Material
SGPNPJ	S25C
STUPDJ	SCS13A

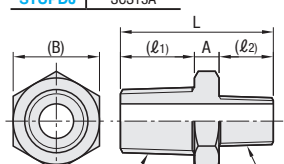

Reducing Tees RoHS10




Type	Material
SGPTDJ	S25C

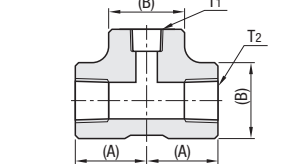

Bushings RoHS10



Type	Material
SGPPBJ	S25C
SUTPBJ	SCS13A

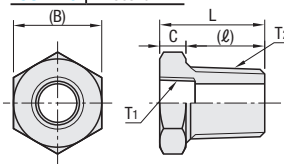

Fitting Specifications

Fitting Material	Steel S25C of JIS G4051 or Equivalent Stainless Steel SUS304TP of JIS G3459 or Equivalent
Max. Operating Temp.	S25C 350°C 0 Ring 100°C SUS30 4800°C
Max. Operating Pressure	20.6MPa
Applicable Pipe	Plumbing with Carbon Steel Pipes, JIS G3454, 3455, 3456 Plumbing with Stainless Steel Pipes, JIS G3459

* S25C material is made of JIS B2316, while SUS304 material is made of JIS B2316.
* As fittings are cast products, (L) dimensions such as (L) and (T) are for reference, not guaranteed.

Part Number		SGPNRJ		SUTNRJ		SGPNRJ		SUTNRJ	
Type	No.	R (PT)	(L)	(L)	(B)	(L)	(B)	Unit Price	Volume Discount Rate
SGPNRJ	6A	1/8	11	27	12	10	28	12	1 ~ 4 pcs.
	8A	1/4	15	35	17	12	34	14	5 ~ 20 pcs.
	10A	3/8	15	37	19	13	36	19	1 ~ 4 pcs.
	15A	1/2	17	43	23	16	42	23	5 ~ 20 pcs.
	20A	3/4	20	49	29	18	47	29	
SUTNRJ	25A	1	22	54	35	20	52	35	
	32A	1 1/4	22	56	46	22	56	46	
	40A	1 1/2	25	62	50	23	60	50	
	50A	2	29	72	63	25	66	63	

For orders larger than indicated quantity, please check with WOS.

Part Number		SGPPUJ		SUTPUJ		SGPPUJ		SUTPUJ	
Type	No.	Rc (PT)	(B)	(L)	(A)	(B)	(L)	(A)	(B)
SGPPUJ	8A	1/4	22	38	18	32	22	38	18
	10A	3/8	26	40	20	41	26	40	20
	15A	1/2	32	44	22	46	32	44	22
	20A	3/4	38	50	26	54	38	50	26
	25A	1	47	56	28	63	47	56	28
SUTPUJ	32A	1 1/4	58	62	30	74	58	62	30
	40A	1 1/2	63	70	32	80	63	70	32
	50A	2	76	76	36	95	76	76	36

For orders larger than indicated quantity, please check with WOS.

For orders larger than indicated quantity, please check with WOS.											
Part Number		Rc (PT)		SGPSDJ		SUTSSJ		SGPSDJ		SUTSSJ	
Type	No.	T1	T2	L	(D)	L	(D)	Unit Price 1 ~ 9 pcs.	Volume Discount Rate 10 ~ 30 pcs.	Unit Price 1 ~ 9 pcs.	Volume Discount Rate 10 ~ 30 pcs.
SGPSDJ	12	1/8	1/4	25	22	28	22				
	23	1/4	3/8	28	28	33	25				
	24	1/4	1/2	32	32	32	32				
	34	3/8	1/2	32	32	37	32				
SUTSSJ	36	3/8	3/4	38	38	42	38				
	46	1/2	3/4	38	38	42	38				
	48	1/2	1	45	46	45	45				
	68	3/4	1	45	46	45	45				