


Pull Handles with Caps / Nylon Pull Handles

Nylon Pull Handles with Caps



UPCDG
(Nylon 6)

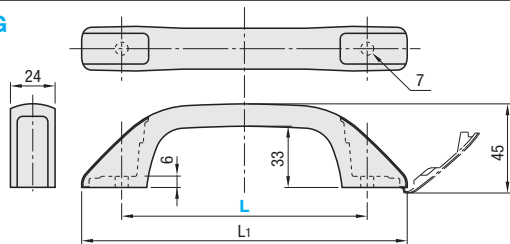


24, 7, 6, 33, 45, L, L1

*Easier mounting is possible by the combination use with the Nuts for Handles below.

M	Material
	Glass Fiber Reinforced Nylon 6

Part Number Type	L	L1	Allowable Load (N)	Mass (g)	Unit Price
UPCDG	90	133	500	30	
	94	136.5		33	
	117	160		36	
	132	175		39	


Pull Handles with Caps

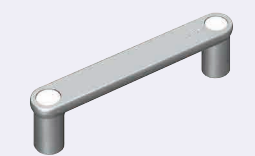

HHDG
HHDGS

Type	Handle	Cap
	M Material S Surface Treatment	M Material Color
HHDG	ADC12	Baked Finish ABS White
HHDGS	SUS304 Equivalent	Buffed Finish ABS White

*Easier mounting is possible by the combination use with the Nuts for Handles below.

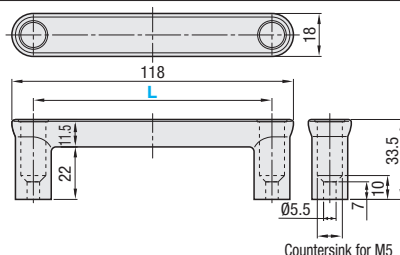

18, 118, L, 11.5, 22, 05.5, 7, 10, 33.5

Countersink for M5

Part Number Type	L	Mass (g)	Set of applicable Screws and Nuts		Unit Price	
			Screw	Quantity	HHDG	HHDGS
HHDG HHDGS	100	62	Flat Head Screw M5	2		

Ordering Example


Part Number

UPCDG90
HHDG100

Nuts for Pull Handles



HHPUW

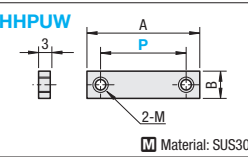

3, A, P, B, 2-M

M Material: SUS304

Part Number Type	P	B	A	M	Handle	Unit Price	Volume Discount Rate
HHPUW	90	10	100	6	UPCDG90		
	100	12	110	5	HHDG100		

Ordering Example


Part Number

HHPUW90

Nylon Pull Handles



UPFN

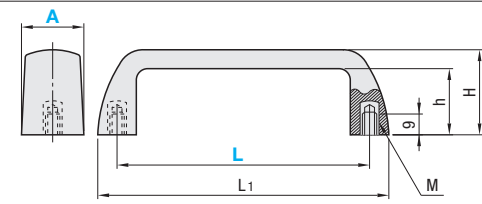

A, L1, H, h, L, M

M	Material
Handle	Glass Fiber Reinforced Nylon 6
Threaded Section	Brass (Insert)

Part Number Type	A	L	Color of Handle	L1	H	h	M (Coarse)	Allowable Load (N)	Mass (g)	Unit Price		
										B (Black)	W (White), M (Orange), R (Red)	
UPFN	26	105	B (Black)	121	37	29	6	500	55			
		110	W (White)						60			
		117	M (Orange) R (Red)						62			

*The default color of handle will be black unless specified.

Ordering Example

Part Number - L - Color of Handle


UPFN26 - 105 - B

Aluminum Tube Pull Handles


Aluminum Tube Pull Handles
- Small Diameter




UWAPNC
UWAPFC (L Configurable Type)

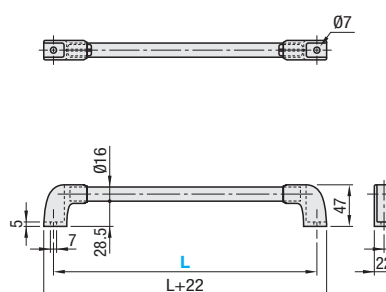

07, 016, 7, 28.5, L, L+22, 47, 11, 22

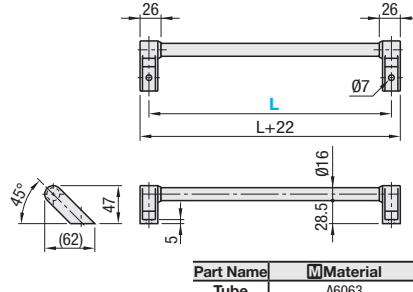

UHFAPC
UHFAPFC (L Configurable Type)

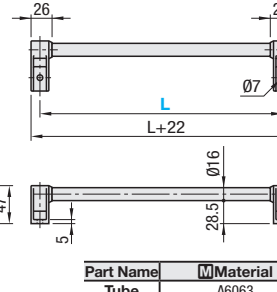

26, 07, L, L+22, 28.5, 016, 47, 11, 22, 45, 62, 5

Part Name	M Material
Tube	A6063
Elbow	Polycarbonate

Part Number Type	L	Set of applicable Screws and Nuts		Unit Price	
		UWAPNC	UHFAPC		
UWAPNC UHFAPC	100	Hex Socket Head Cap Screw M6			
	150				
	200				
	250				
	300				

Ordering Example

Part Number

UWAPNC200
UWAPFC-237


* For L Dimensions, add "-" (hyphen).

Part Number Type	L 1mm Increment	Set of applicable Screws and Nuts		Unit Price	
		UWAPFC	UHFAPFC		
UWAPFC UHFAPFC	100~150	Hex Socket Head Cap Screw M6			
	151~200				
	201~250				
	251~300				


Aluminum Tube Pull Handles




UWAPN
UWAPF (L Configurable Type)

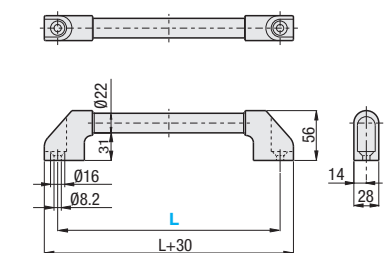

022, 31, 016, 08.2, L, L+30, 56, 14, 28

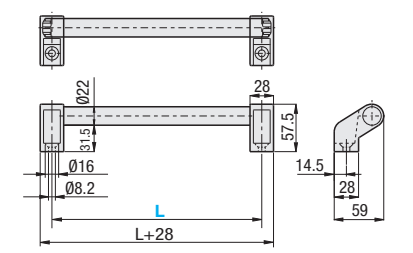

UHFAPF
UHFAPF (L Configurable Type)

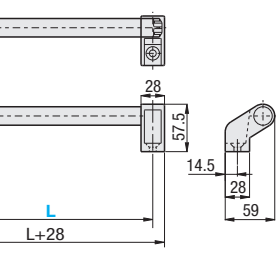

022, 28, 31.5, 016, 08.2, L, L+28, 57.5, 14.5, 28, 59

Part Name	M Material
Tube	A6063
Elbow	Glass Fiber Reinforced Nylon

Part Number Type	L	Set of applicable Screws and Nuts		Unit Price	
		UWAPN	UHFAP		
UWAPN UHFAP	150	Flat Head Screw M8			
	200				
	250				
	300				
	400				
	500				
	600				

Ordering Example

Part Number

UWAPN150
UHFAPF-185

* For L Dimensions, add "-" (hyphen).

Part Number Type	L 1mm Increment	Set of applicable Screws and Nuts		Unit Price	
		UWAPF	UHFAPF		
UWAPF UHFAPF	100~150	Flat Head Screw M8			
	151~200				
	201~250				
	251~300				
	301~400				
	401~500				
	501~600				