


# Economy Panel Clamps

Points to compare against Similar Products | By adopting PVC as the material, economical pricing has been achieved.

For the similar products, see P815

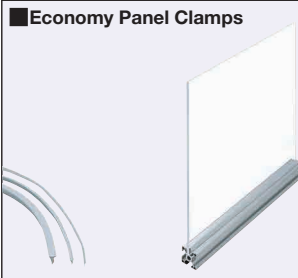

Type	Color	Material	Heat Resistant Temp.
NSCP	Light Gray	PVC	-25~80°C


NSCP3H serves to fix 5 Series Aluminum Extrusions as well as 6 Series ones.  
 HSCP uses the other material than HSCPF (P815) and thus, differs from HSCPF in the color tone of Light Gray. In addition, on the lower part of the back surface of these two part number products, the thin groove is machined to distinguish between them.

For 5mm Thickness Panel

5 Series

NSCP1H

 S (Light Gray)



6 Series

NSCP3H


S (Light Gray)



8, 8-45 Series

NSCP5H

 S (Light Gray)




For 3mm Thickness Panel

5 Series

NSCP3H

 
S (Light Gray)



6 Series

NSCP5HN

 
S (Light Gray)



8, 8-45 Series

NSCP7H

 S (Light Gray)




### Standard Length

Part Number	Color	Length m	Applicable Extrusion (Series)	Applicable Panel Thickness	Length 6m		Length 12m		
					Unit Price	Volume Discount Rate	Unit Price	Volume Discount Rate	
NSCP	S (Light Gray)	6 12	5 Series	5	1 ~ 8 pc(s).	9~50	1 ~ 8 pc(s).	9~50	
					6 Series	3			
						5			
						3			
						5			
8 Series 8-45 Series	3								

Ordering Example: Part Number - Color - Length  
 NSCP3H - S - 12

### How to select Panel Clamps and Economy Panel Clamps (App. Example)

Panel Plate Thickness 5mm			
Extrusion	HFS5	HFS6	HFS8 HFS8-45
Drawing	HSCP1H HSCPF1H NSCP1H	HSCP3H HSCPF3H NSCP3H	HSCP5H HSCPF5H NSCP5H
Panel Plate Thickness 3mm			
Extrusion	HFS5	HFS6	HFS8 HFS8-45
Drawing	HSCP3H HSCPF3H NSCP3H	HSCP5HN HSCPF5HN NSCP5HN	HSCP7H HSCPF7H NSCP7H

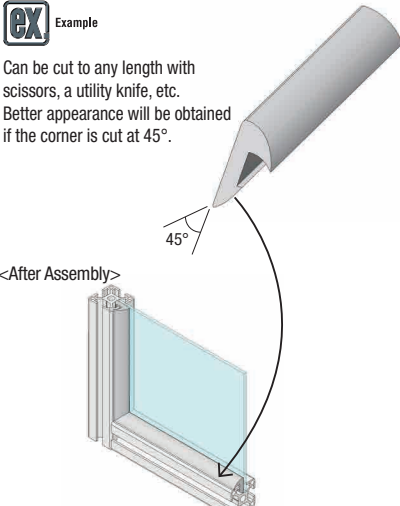

<After Assembly>

