




JUNCTION BOX FOR SWITCH SIGNAL

JUNCTION BOX FOR SWITCH SIGNAL

■ 4-In-1-Out Junction Box for Switch Signal



MAJB4

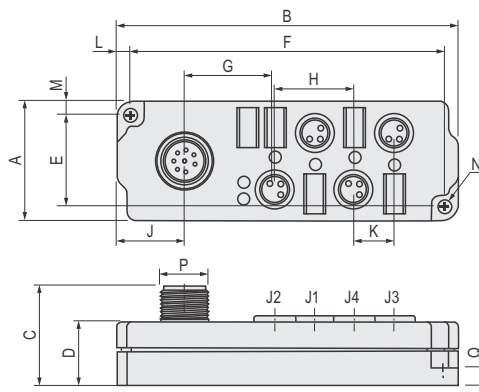

Part Number		V type outlet mode (Vertical)	A	B	C	D	E	F	G	H	J	K	L	M	N	P	Q	Applicable connector model	Weight (g)
Type	Switch type																		
MAJB4	N (NPN Switch)	M12	30	86	25	16	23	79	22.8	20	17	10	3.5	3.5	φ 3.5	M12×1	4.5	MELKB4—M12 MELKC4—M12 MELKD4—M8	110
	P (PNP Switch)																		



Order

Part Number — V
MAJB4N — M12



Price

Quotation


Days
to Ship

Quotation

■ 3-Pin Signal Box Connector



 MELKD4




Part Number	M fixing thread	A	B	C	D	Applicable junction box
MELKD4	M8	35.5	25.5	φ15	M12×1	MAJC8 MAJD8 MAJB4

■ 14-Pin Signal Box Cable Connector



MELKB4

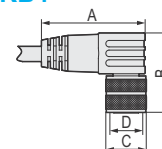


Part Number	M fixing thread	A	B	C	D	Applicable junction box
MELKB4	M12	48.8	37	φ19	M16×0.75	MAJC8

■ 8-Pin Signal Box Cable Connector



MELKC4

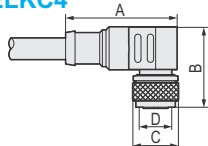


Part Number	M fixing thread	A	B	C	D	Applicable junction box
MELKC4	M12	35	φ19.6	40	M12×1	MAJB4

■ 8-Pin Signal Box Connector



MELKE8

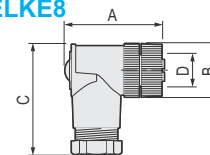

Part Number	M fixing thread	A	B	C	Applicable junction box
MELKE8	M16	47	φ12	M8×1	MAJB4



Order

Part Number — M
MELKD4 — M8
MELKB4 — M12
MELKC4 — M12
MELKE8 — M16



Price

Quotation

Days
to Ship

Quotation

REMOVAL
RELATED PRODUCTS