


HEAT RETAINING COVER FOR HOPPER DRYER HOSE

shows in red


■ Application Use to keep the hopper dryer hose warm.

■ Heat Retaining Cover
(For hopper dryer hose)



■ When in Use

M-DHI

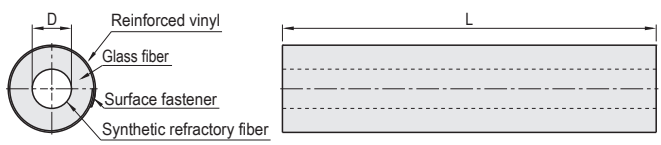

- Inner material: Synthetic refractory fiber (max. 315°C)
- Outer material: Reinforced vinyl
- Lining material: Glass fiber 25 mm (heat insulating material: max. 454°C)
- Fastener: Surface fastener

| L (mm) | Applicable outer dia. of hose (φ) | Part Number | | Unit Price |
|-----------|---|-------------|-------|------------|
| | | Type | D (φ) | 1~3 pcs |
| 600 | 35~ 41 | M-DHI | 38 | Quotation |
| | 47~ 53 | | 50 | |
| | 60~ 66 | | 63 | |
| | 73~ 79 | | 76 | |
| | 97~103 | | 100 | |
| | 112~118 | | 115 | |
| | 127~133 | | *130 | |
| | 137~143 | | *140 | |
| | 147~153 | | *150 | |

ⓘ The color may change to blue depending on the specified size.

■ Features

- Depending on the work environment and ambient temperature, heat loss is about 14°C per 300 mm hopper dryer hose can be prevented.
- The applicable hose dimensions can be adjusted by surface fastener (width: 20 mm).



Order

Part Number

M-DHI-38



Days to Ship

Quotation



Price

Quotation